

Silkscreen bottom



(408) 435-1800  
www.iliteev.com

\* See Quick Start Guide

-H	8A-38A*	48A012V
-E	8A-38A	15A02V (18A04V)*
-L	8A-38A	32A050V (2A012V)*
-E	38A-15A	2A015V
-D	18A-15A	57A04V
-C	18A-15A	15A08V
-B	18A-15A	2A052V
-V	34A-12A	32A020V
VERSIONS	+VIN	+AOUT


\*\*

-VIN

Lp5



CIN3

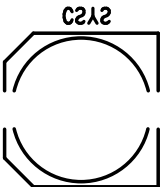


C212

Lp2



Lp8

-AOUT

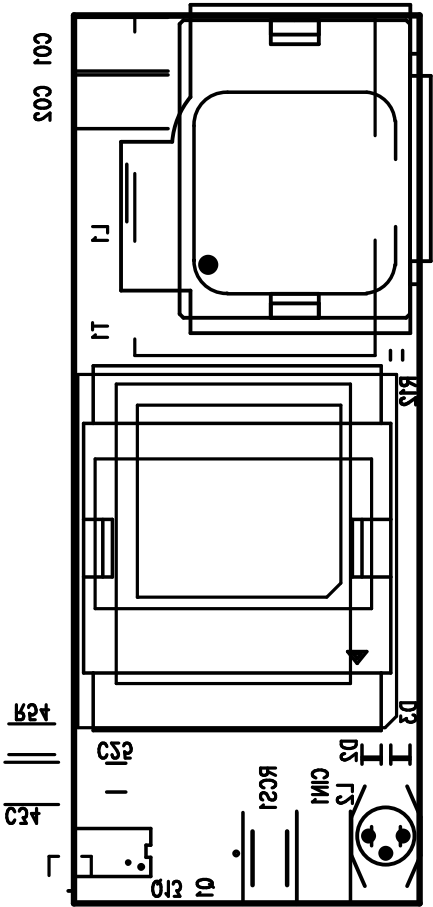

Lp4



Lp3

+AOUT\*\*

+VIN\*\*

Lp1

DEMO CIRCUIT 1311A-  
ISOLATED FORWARD DC\DC CONVERTER  
T11025EGN-1' T14430E26