



**DOCUMENT TYPE:** POD

**DOCUMENT ID #:** 21-100779

**REVISION:** A-000

**DOCUMENT TITLE:** PACKAGE OUTLINE 30 BUMPS WLP PKG. 0.4 mm

**EFFECTIVE DATE:** 07/30/2024

**EXPIRATION DATE:**

**CHANGE NUMBER:** 1213557

**ORIGINATOR:** Shaira Isabel Torre

**REASON FOR CHANGE:**  
Initial Release

**DOCUMENT TYPE:** POD

**DOCUMENT ID #:** 21-100779

**REVISION:** A-000

**DOCUMENT TITLE:** PACKAGE OUTLINE 30 BUMPS WLP PKG. 0.4 mm

**EFFECTIVE DATE:** 07/30/2024



**EXPIRATION DATE:**

**CHANGE NUMBER:** 1213557



**ORIGINATOR:** Shaira Isabel Torre

**REASON FOR CHANGE:**  
Initial Release

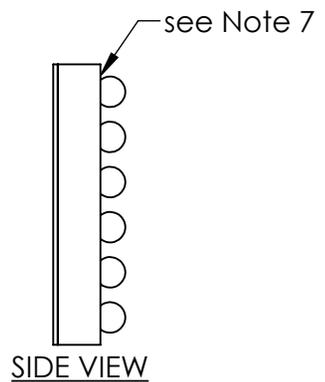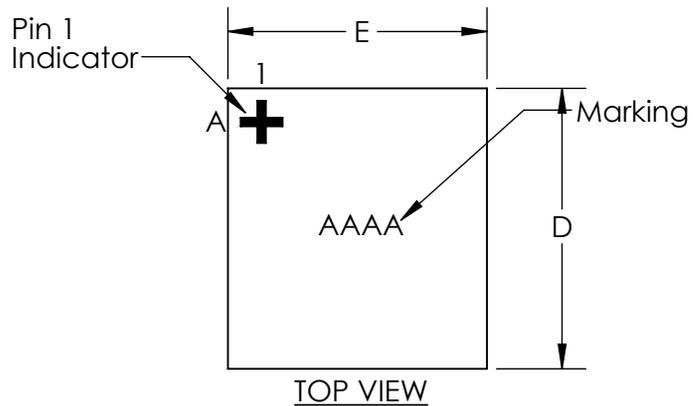

COMMON DIMENSIONS	
A	0.64 ±0.05
A1	0.22 ±0.03
A2	0.42 REF
A3	0.04 BASIC
b	∅0.27 ±0.03
D	2.488 ±0.025
E	2.298 ±0.025
D1	2.00 BASIC
E1	1.60 BASIC
e	0.40 BASIC
SD	0.00 BASIC
SE	0.20 BASIC
DEPOPULATED BUMPS: NONE	

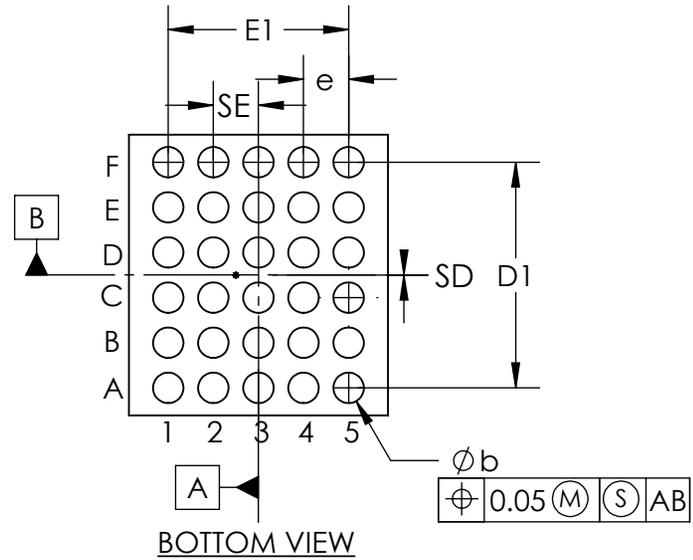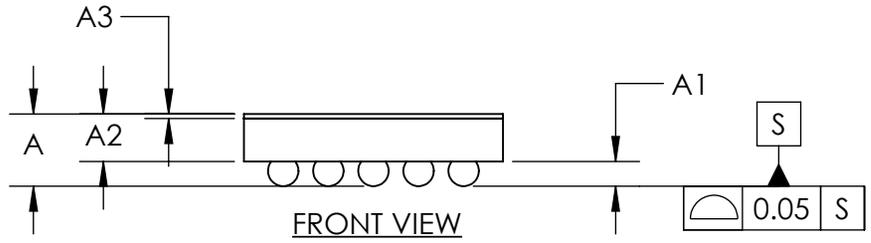

- NOTES:
1. Terminal pitch is defined by terminal center to center value.
  2. Outer dimension is defined by center lines between scribe lines.
  3. All dimensions in millimeter.
  4. Marking shown is for package orientation reference only.
  5. Tolerance is ± 0.02 unless specified otherwise.
  6. All dimensions apply to PbFree (+) package codes only.
  7. Front - side finish can be either Black or Clear.

- DRAWING NOT TO SCALE -

TITLE PACKAGE OUTLINE 30 BUMPS WLP PKG. 0.4 mm PITCH, W302V2Z+1		
APPROVAL	DOCUMENT CONTROL NO. 21-100779	REV. A 1/1

