


# Package Dimensions

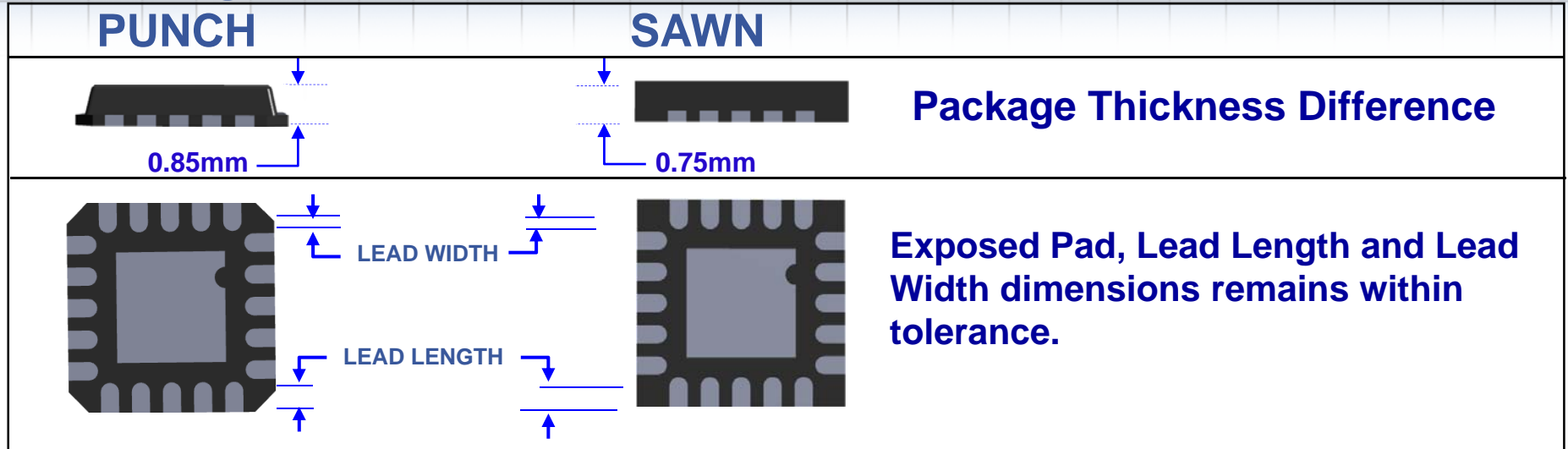


Body Size (mm)	Lead Count	Lead Pitch (mm)	Punch LFCSP POD	Sawn LFCSP POD	Exposed Pad Size (mm)
4 x 4	16	0.65	CP 16-16	CP 16-34	1.8 x 1.8
			CP 16-4	CP 16-23	2.3 x 2.3
			CP 16-10	CP 16-20	2.35 x 2.35
			CP 16-13	CP 16-26	2.5 x 2.5
	20	0.5	CP 20-1	CP 20-6	2.1 x 2.1
			CP 20-3	CP 20-7	2.3 x 2.3
			CP 20-4	CP 20-10	2.5 x 2.5
	24	0.5	CP 24-1	CP 24-10	2.1 x 2.1
			CP 24-13 CP 24-2	CP 24-14	2.3 x 2.3
			CP 24-3	CP 24-7	2.5 x 2.5


# Package Outline Drawing (POD) Dimensional Analysis

Body Size (mm)	Lead Count	Punch Type LFCSP				Sawn Type LFCSP			
		POD Spec	E-Pad Size (mm SQ.)	Lead Length (mm)	Lead Width (mm)	POD Spec	E-Pad Size (mm SQ.)	Lead Length (mm)	Lead Width (mm)
4x4	16	CP 16-16	1.8 ± 0.15	0.60 <sup>+0.15</sup> <sub>-0.10</sub>	0.30 ±0.05	CP 16-34	1.8 ± 0.15	0.60 <sup>+0.15</sup> <sub>-0.10</sub>	0.30 ±0.05
		CP 16-4	2.3 ± 0.15	0.60 <sup>+0.15</sup> <sub>-0.10</sub>	0.30 ±0.05	CP 16-23	2.3 ± 0.15	0.60 ±0.10	0.30 ±0.05
		CP 16-10	2.35 ± 0.15	0.40 ±0.10	0.30 ±0.05	CP 16-20	2.35 ±0.10	0.40 ±0.10	0.30 ±0.05
		CP 16-13	2.5 ± 0.15	0.40 ±0.10	0.23 <sup>+0.07</sup> <sub>-0.05</sub>	CP 16-26	2.5 ±0.10	0.40 ±0.10	0.30 ±0.05
4x4	20	CP 20-1	2.1 ± 0.15	0.60 <sup>+0.15</sup> <sub>-0.10</sub>	0.23 <sup>+0.07</sup> <sub>-0.05</sub>	CP 20-6	2.1 ±0.10	0.60 ±0.05	0.25 <sup>+0.05</sup> <sub>-0.07</sub>
		CP 20-3	2.3 ± 0.15	0.40 ±0.10	0.23 <sup>+0.07</sup> <sub>-0.05</sub>	CP 20-7	2.3 ± 0.15	0.40 ±0.10	0.25 <sup>+0.05</sup> <sub>-0.07</sub>
		CP 20-4	2.5 ± 0.15	0.40 ±0.10	0.23 <sup>+0.07</sup> <sub>-0.05</sub>	CP 20-10	2.5 ±0.15	0.40 ±0.10	0.25 ±0.05
4x4	24	CP 24-1	2.1 ± 0.15	0.40 ±0.10	0.23 <sup>+0.07</sup> <sub>-0.05</sub>	CP 24-10	2.1 ±0.10	0.40 ±0.10	0.25 <sup>+0.05</sup> <sub>-0.07</sub>
		CP 24-13	2.3 ±0.10	0.40 ±0.10	0.23 <sup>+0.07</sup> <sub>-0.05</sub>	CP 24-14	2.3 ±0.10	0.40 ±0.10	0.25 <sup>+0.05</sup> <sub>-0.07</sub>
		CP 24-2	2.3 ±0.15	0.40 ±0.10	0.23 <sup>+0.07</sup> <sub>-0.05</sub>	CP 24-14	2.3 ±0.10	0.40 ±0.10	0.25 <sup>+0.05</sup> <sub>-0.07</sub>
		CP 24-3	2.5 ± 0.15	0.40 ±0.10	0.23 <sup>+0.07</sup> <sub>-0.05</sub>	CP 24-7	2.5 ±0.15	0.40 ±0.10	0.25 <sup>+0.05</sup> <sub>-0.07</sub>

**LEGEND:**



Tighter (Better)



Standardized