


Package Dimensions

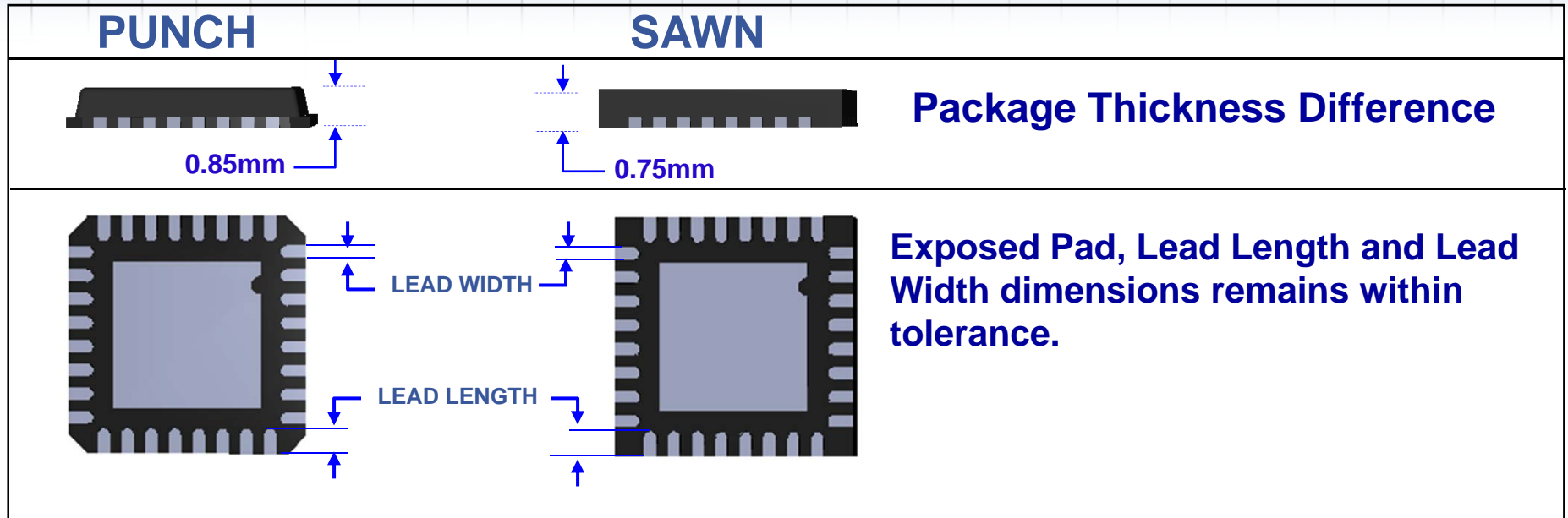

Body Size (mm)	Lead Count	Lead Pitch (mm)	Punch LFCSP POD	Sawn LFCSP POD	Exposed Pad Size (mm)
5 x 5	16	0.8	CP 16-6	CP 16-31	3.1 x 3.1
	20	0.65	CP 20-5	CP 20-9	3.1 x 3.1
	32	0.5	CP 32-8	CP 32-21	2.7 x 2.7
			CP 32-2	CP 32-7	3.1 x 3.1
			CP 32-3	CP 32-13	3.3 x 3.3
			CP 32-4	CP 32-11	3.5 x 3.5

Package Outline Drawing (POD) Dimensional Analysis

Body Size (mm)	Lead Count	Punch Type LFCSP				Sawn Type LFCSP			
		POD Spec	E-Pad Size (mm SQ.)	Lead Length (mm)	Lead Width (mm)	POD Spec	E-Pad Size (mm SQ.)	Lead Length (mm)	Lead Width (mm)
5x5	16	CP 16-6	3.1 ± 0.15	0.60 ^{+0.15} _{-0.10}	0.30 ±0.05	CP 16-31	3.1 ± 0.15	0.60 ^{+0.15} _{-0.10}	0.30 ±0.05
5x5	20	CP 20-5	3.1 ± 0.10	0.60 ^{+0.15} _{-0.10}	0.28 ^{+0.07} _{-0.05}	CP 20-9	3.1 ±0.15	0.60 ^{+0.15} _{-0.20}	0.28 ^{+0.07} _{-0.05}
5x5	32	CP 32-8	2.7 ± 0.15	0.40 ±0.10	0.25 ^{+0.05} _{-0.07}	CP 32-21	2.7 ±0.10	0.40 ±0.10	0.25 ^{+0.05} _{-0.07}
		CP 32-2	3.1 ± 0.15	0.40 ±0.15	0.25 ^{+0.05} _{-0.07}	CP 32-7	3.1 ±0.15	0.40 ±0.10	0.25 ^{+0.05} _{-0.07}
		CP 32-3	3.3 ±0.15	0.40 ±0.10	0.25 ^{+0.05} _{-0.07}	CP 32-13	3.3 ±0.15	0.40 ±0.10	0.25 ^{+0.05} _{-0.07}
		CP 32-4	3.5 ± 0.15	0.40 ±0.10	0.25 ^{+0.05} _{-0.07}	CP 32-11	3.5 ^{+0.15} _{-0.10}	0.40 ±0.10	0.25 ^{+0.05} _{-0.07}