

- Electrical Properties:

Frequency Range: 2.4~2.5 GHz

Impedance: 50Ω nominal

VSWR: <2.0:1

Gain: 2 dBi

Radiation: Omni

Polarization: Vertical
- Mechanical Properties:

Connector: MMCX right angle plug

Material: RG178 coaxial


Cable: Polyurethane(Black)

CAP: Brass with silver plating

Antenna Body: Brass with silver plating

Operation Temp.: -20°C to +65°C

Storage Temp.: -30°C to +75°C

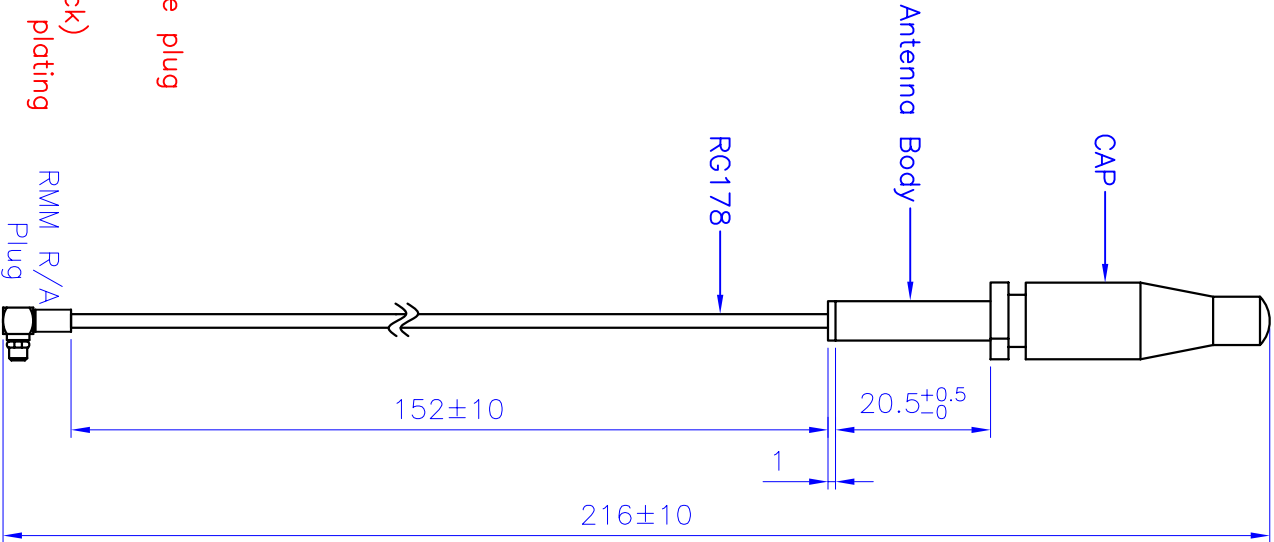

TITLE	2.4Hz Antenna with CAP		Rev. Date	Sheet
	Customer Model		10/23/06	1 of 1
UNIT	DWG. NO.	S152CL-03251		
mm				
SCALE				
NONE				

NEARSON

NEARSON